

StrongHold™ Screw Applied Cable Tie Mounts

StrongHold™ Screw Applied Cable Tie Mounts are designed to increase your installation speed while keeping your costs low. Our mounts are UL recognized and come in a variety of sizes and styles. Paired with StrongHold™ cable ties, our screw applied mounts offer you the best wire routing solution for your application needs.

Low Profile Cable Tie Anchor Mounts

StrongHold Low Profile Anchor Cable Tie Mounts are a mounting solution for applications where overhead space is limited and the bundle needs to remain close to the mounting surface.



Part Number	Material	Used with Stronghold Cable Ties	Hole Diameter In. (mm)	Length In. (mm)	Width In. (mm)	Height In. (mm)	Mounting Method	Std. Pkg. Qty.	Min. Order Qty.
SSMTA-M	Nylon 6.6	S*-18, S*-40, S*-50	0.17 (4.3)	0.75 (19.0)	0.38 (9.5)	0.20 (5.1)	#8 (M4) Screw	1000	500
SSMTA-C	Nylon 6.6	S*-18, S*-40, S*-50	0.17 (4.3)	0.75 (19.0)	0.38 (9.5)	0.20 (5.1)	#8 (M4) Screw	100	500

Standard Screw Applied Cable Tie Mounts

StrongHold™ Standard Screw Applied Cable Tie Mounts provide maximum stability for cable bundles and have a low profile to keep bundles close to the mounting surface.



Part Number	Material	Used with Stronghold Cable Ties	Hole Diameter In. (mm)	Length In. (mm)	Width In. (mm)	Height In. (mm)	Mounting Method	Std. Pkg. Qty.	Min. Order Qty.
SSM2S6-M	Nylon 6.6	S*-18, S*-40, S*-50	0.29 (7.1)	0.63 (16.0)	0.43 (10.8)	0.28 (7.0)	#6 (M3) Screw	1000	500
SSM2S6-C	Nylon 6.6	S*-18, S*-40, S*-50	0.29 (7.1)	0.63 (16.0)	0.43 (10.8)	0.28 (7.0)	#6 (M3) Screw	100	500
SSM2S6-3X	Nylon 6.6	S*-18, S*-40, S*-50	0.29 (7.1)	0.63 (16.0)	0.43 (10.8)	0.28 (7.0)	#6 (M3) Screw	30	300
SS2S6-M0	Weather Resistant Nylon 6.6	S*-18, S*-40, S*-50	0.29 (7.1)	0.63 (16.0)	0.43 (10.8)	0.28 (7.0)	#6 (M3) Screw	1000	500
SSM2S6-C0	Weather Resistant Nylon 6.6	S*-18, S*-40, S*-50	0.29 (7.1)	0.63 (16.0)	0.43 (10.8)	0.28 (7.0)	#6 (M3) Screw	100	500
SSM2S6-3X0	Weather Resistant Nylon 6.6	S*-18, S*-40, S*-50	0.29 (7.1)	0.63 (16.0)	0.43 (10.8)	0.28 (7.0)	#6 (M3) Screw	30	300
SSM3S8-M	Nylon 6.6	S*-18, S*-40, S*-50, S*-120	0.32 (8.1)	0.86 (21.9)	0.61 (15.5)	0.37 (9.4)	#8 (M4) Screw	1000	500
SSM3S8-C	Nylon 6.6	S*-18, S*-40, S*-50, S*-120	0.32 (8.1)	0.86 (21.9)	0.61 (15.5)	0.37 (9.4)	#8 (M4) Screw	100	500
SSM3S8-3X	Nylon 6.6	S*-18, S*-40, S*-50, S*-120	0.32 (8.1)	0.86 (21.9)	0.61 (15.5)	0.37 (9.4)	#8 (M4) Screw	30	300
SSM3S8-M0	Weather Resistant Nylon 6.6	S*-18, S*-40, S*-50, S*-120	0.32 (8.1)	0.86 (21.9)	0.61 (15.5)	0.37 (9.4)	#8 (M4) Screw	1000	500
SSM3S8-C0	Weather Resistant Nylon 6.6	S*-18, S*-40, S*-50, S*-120	0.32 (8.1)	0.86 (21.9)	0.61 (15.5)	0.37 (9.4)	#8 (M4) Screw	100	500
SSM3S8-3X0	Weather Resistant Nylon 6.6	S*-18, S*-40, S*-50, S*-120	0.32 (8.1)	0.86 (21.9)	0.61 (15.5)	0.37 (9.4)	#8 (M4) Screw	30	300

Low Profile Screw Applied Cable Tie Mounts

StrongHold™ Low Profile Screw Applied Cable Tie Mounts are designed to keep bundles close to the mounting surface and are ideal for application where space is limited.



Part Number	Material	Used with Stronghold Cable Ties	Hole Diameter In. (mm)	Length In. (mm)	Width In. (mm)	Height In. (mm)	Mounting Method	Std. Pkg. Qty.	Min. Order Qty.
SSMLP-M	Nylon 6.6	S*-18, S*-40, S*-50	0.164 (4.2)*	0.75 (19.1)	0.50 (12.7)	0.12 (3.0)	#8 (M4) Countersunk Screw	1000	500
SSMLP-C	Nylon 6.6	S*-18, S*-40, S*-50	0.164 (4.2)*	0.75 (19.1)	0.50 (12.7)	0.12 (3.0)	#8 (M4) Countersunk Screw	100	500
SSMLP-3X	Nylon 6.6	S*-18, S*-40, S*-50	0.164 (4.2)*	0.75 (19.1)	0.50 (12.7)	0.12 (3.0)	#8 (M4) Countersunk Screw	30	300


See customer drawing for countersunk hole reference dimensions.

StrongHold™ Cable Tie Accessories

Adhesive Backed Mounts

StrongHold™ 4-way adhesive backed cable tie mounts are mounted with rubber-based adhesive foam tape. The adhesive backing provides a dependable method for securing wires and cables quickly and are an alternative to mechanical fasteners, providing lower installed cost.

- Designed to provide reliable bond for mounting wires and cables when a hole cannot be drilled.
- 4-way tie entry allows for quick and easy installation of StrongHold™ Cable Ties
- Recommended surfaces include: plastic, wood, painted surfaces, powder coating, metal ad paper
- Not recommended for use on concrete, stone or masonry

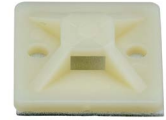

Part Number	Material	Used with Stronghold Cable Ties	Size (LxW) (mm)	Size (LxW) (In)	Std.Pkg. Qty.	Min. Order Qty.
SMP12A-3X	Nylon 6.6	S*-18, S*-40	.787x.787	20x20	30	300pcs
SMP12A-C	Nylon 6.6	S*-18, S*-40	.787x.787	20x20	100	1000pcs
SMP12A-M	Nylon 6.6	S*-18, S*-40	.787x.787	20x20	1000	5000pcs
SMP16A-3X	Nylon 6.6	S*-18, S*-40, S*-50	1" X 1"	25x25	30	300pcs
SMP16A-C	Nylon 6.6	S*-18, S*-40, S*-50	1" X 1"	25x25	100	1000pcs
SMP16A-M	Nylon 6.6	S*-18, S*-40, S*-50	1" X 1"	25x25	1000	5000pcs
SMP18A-3X	Nylon 6.6	S*-18, S*-40, S*-50	1.18x1.18	30x30	30	300pcs
SMP18A-C	Nylon 6.6	S*-18, S*-40, S*-50	1.18x1.18	30x30	100	1000pcs
SMP18A-M	Nylon 6.6	S*-18, S*-40, S*-50	1.18x1.18	30x30	1000	5000pcs
SMP12A-3X0	Nylon 6.6 (Black)	S*-18, S*-40	.787x.787	20x20	30	300pcs
SMP12A-C0	Nylon 6.6 (Black)	S*-18, S*-40	.787x.787	20x20	100	1000pcs
SMP12A-M0	Nylon 6.6 (Black)	S*-18, S*-40	.787x.787	20x20	1000	5000pcs
SMP16A-3X0	Nylon 6.6 (Black)	S*-18, S*-40, S*-50	1" X 1"	25x25	30	300pcs
SMP16A-C0	Nylon 6.6 (Black)	S*-18, S*-40, S*-50	1" X 1"	25x25	100	1000pcs
SMP16A-M0	Nylon 6.6 (Black)	S*-18, S*-40, S*-50	1" X 1"	25x25	1000	5000pcs
SMP18A-3X0	Nylon 6.6 (Black)	S*-18, S*-40, S*-50	1.18x1.18	30x30	30	300pcs
SMP18A-C0	Nylon 6.6 (Black)	S*-18, S*-40, S*-50	1.18x1.18	30x30	100	1000pcs
SMP18A-M0	Nylon 6.6 (Black)	S*-18, S*-40, S*-50	1.18x1.18	30x30	1000	5000pcs

Complimentary Products

StrongHold™ Cable Accessories are most effective when used with StrongHold™ Cable Ties. Our cable tie line features a variety of sizes in locking, releasable and clamp ties. These various styles of cable ties are offered in natural plenum-rated, UV weather resistant black, and red, suitable for indoor and outdoor applications.



WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT US/CANADA
Phone: 800.777.3300

PANDUIT EUROPE LTD.
London, UK
cs-emea@panduit.com
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.
Republic of Singapore
cs-ap@panduit.com
Phone: 65.6305.7575

PANDUIT JAPAN
Tokyo, Japan
cs-japan@panduit.com
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA
Guadalajara, Mexico
cs-la@panduit.com
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.
Victoria, Australia
cs-aus@panduit.com
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to www.panduit.com/warranty

For more information

Visit us at www.panduit.com

Contact Customer Service by email: cs@panduit.com
or by phone: 800.777.3300

PANDUIT®

©2020 Panduit Corp.
ALL RIGHTS RESERVED.
CTCB75--SA-ENG
9/2020